


# Intermediate plate MUH-ZP-D-3-24G

Part number: 34934

FESTO

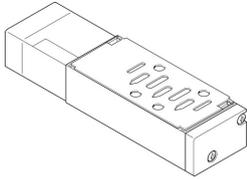

## Data sheet

Feature	Value
Nominal width	14.5 mm
Width dimension	72 mm
Type code	MUH
Actuation type	Electrical
Mounting position	Any
Manual override	Non-detenting
Reset method	Mechanical spring
Type of control	Direct
Flow direction	Non-reversible
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure	2 bar ... 10 bar
Nominal operating voltage DC	24 V
Permissible voltage fluctuations	+/- 10 %
Certification	c UL us - Recognized (OL)
CE marking (see declaration of conformity)	As per EU EMC directive
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-20 °C ... 40 °C
Temperature of medium	-5 °C ... 50 °C
Degree of protection	IP65
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Ambient temperature	-5 °C ... 50 °C
Product weight	500 g
Type of mounting	With through-hole
Note on materials	RoHS-compliant
Seals material	NBR