


Vacuum suction cup VASB-8-M5-NBR

FESTO

Part number: 35410

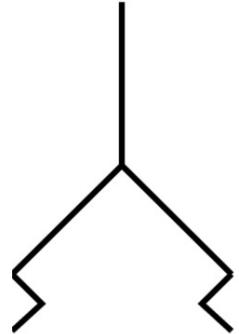

Data sheet

Feature	Value
Nominal width	2 mm
Suction cup diameter	8 mm
Effective suction cup diameter	5.5 mm
Type code	VASB
Connection position	Top
Symbol	00991485
Suction cup shape	Round bellows, 1.5 convolutions
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Ambient temperature	-20 °C ... 80 °C
Breakaway force at 70% vacuum	1.6 N
Holding force at nominal operating pressure	1.6 N
Mounting thread	M5
Suction cup mounting	M5
Vacuum connection	M5
Color	Black
Shore hardness	60 +/- 5
Material of screwed trunnion	Brass
Note on materials	RoHS-compliant
Suction cup material	NBR