


Vacuum suction cup VASB-75-1/4-NBR

Part number: 35415

FESTO

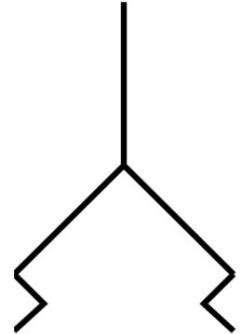

Data sheet

Feature	Value
Nominal width	4 mm
Suction cup diameter	75 mm
Effective suction cup diameter	60 mm
Type code	VASB
Connection position	Top
Symbol	00991485
Suction cup shape	Round bellows, 1.5 convolutions
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Ambient temperature	-20 °C ... 80 °C
Breakaway force at 70% vacuum	197 N
Holding force at nominal operating pressure	197 N
Mounting thread	G $\frac{1}{4}$
Suction cup mounting	G 1/4
Vacuum connection	G1/4
Color	Black
Shore hardness	60 +/- 5
Material of screwed trunnion	Die-cast zinc
Note on materials	RoHS-compliant
Suction cup material	NBR