


Mounting plate VAME-S7-P-N-V14-A

Part number: 3581412

FESTO

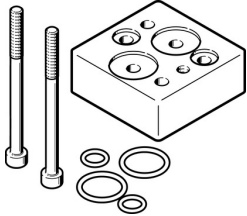

Data sheet

Feature	Value
Type code	VAME
Mounting position	Any
Operating pressure	0 bar ... 10 bar
Operating pressure	0 psi ... 145 psi
Explosion prevention and protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air as per ISO 8573-1:2010 [-:--]
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
Degree of protection	IP65
Type of mounting	With through-hole
Pneumatic connection 1	M5 NAMUR connection diagram
Pneumatic connection 2	Flange 1/4 NAMUR connection diagram
Pneumatic connection 3	G1/4
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Seals material	NBR
Plate material	Aluminum, ematal coated