


# Barbed elbow fitting LCNH-1/8-PK-4

Part number: 35986

FESTO

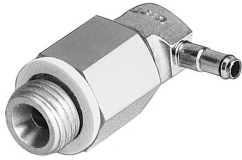

## Data sheet

| Feature                                         | Value                                                              |
|-------------------------------------------------|--------------------------------------------------------------------|
| Nominal width                                   | 2.9 mm                                                             |
| Type code                                       | LCNH                                                               |
| Type of seal on screwed trunnion                | Sealing ring                                                       |
| Operating pressure for entire temperature range | -0.95 bar ... 10 bar                                               |
| Operating medium                                | Compressed air as per ISO 8573-1:2010 [7::-]                       |
| Information on operating and pilot media        | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)                | 2 - Moderate corrosion stress                                      |
| Ambient temperature                             | 0 °C ... 60 °C                                                     |
| Pneumatic connection 1                          | External thread G1/8                                               |
| Pneumatic connection 2                          | for pneumatic tubing outside diameter 6 mm                         |
| Note on materials                               | RoHS-compliant                                                     |
| Housing material                                | Aluminum<br>Die-cast zinc                                          |