


# Axial kit EAMM-A-S38-57A-G2

Part number: 3637956

FESTO

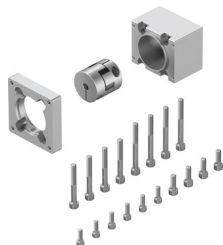

## Data sheet

| Feature                  | Value            |
|--------------------------|------------------|
| Type code                | EAMM-A           |
| Mounting position        | Any              |
| Storage temperature      | -25 °C ... 60 °C |
| Relative air humidity    | 0 - 95 %         |
| Degree of protection     | IP40             |
| Ambient temperature      | -10 °C ... 60 °C |
| Transferable torque      | 6.5 Nm           |
| Product weight           | 340 g            |
| Interface code, actuator | S38              |
| Interface code, motor in | 57A              |
| Note on materials        | RoHS-compliant   |