


Bellow cylinder EB-165-65

Part number: 36487

FESTO

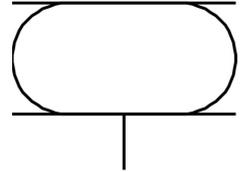

Data sheet

| Feature | Value |
|--|--|
| Size | 165 |
| Required installation Ø | 180 mm |
| Stroke | 65 mm |
| Max. height, advanced | 115 mm |
| Max. angle of inclination | 20 deg |
| Max. offset | 10 mm |
| Min. installation height | 51 mm |
| Type code | EB |
| Mode of operation | Single-acting |
| Symbol | 00991205 |
| Operating pressure | 0 bar ... 8 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [:-:4] |
| Information on operating and pilot media | Operation with oil lubrication not possible |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Ambient temperature | -40 °C ... 70 °C |
| Resetting force | 200 N |
| Product weight | 1200 g |
| Type of mounting | With internal thread |
| Pneumatic connection | G1/4 |
| Note on materials | Free of copper and PTFE RoHS-compliant |
| Bellows material | NR/BR |
| Housing material | Steel Galvanized |