


# Bellow cylinder EB-250-85

Part number: 36489

FESTO

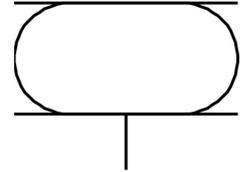

## Data sheet

Feature	Value
Size	250
Required installation $\varnothing$	265 mm
Stroke	85 mm
Max. height, advanced	140 mm
Max. angle of inclination	20 deg
Max. offset	10 mm
Min. installation height	51 mm
Type code	EB
Mode of operation	Single-acting
Symbol	00991205
Operating pressure	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:4]
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-40 °C ... 70 °C
Resetting force	200 N
Product weight	2300 g
Type of mounting	With internal thread
Pneumatic connection	G3/4
Note on materials	Free of copper and PTFE RoHS-compliant
Bellows material	NR/BR
Housing material	Steel Galvanized