
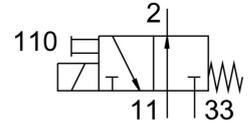


# Air solenoid valve MOFH-3-M5

Part number: 4543

FESTO

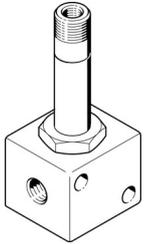

## Data sheet

Feature	Value
Valve function	3/2, open, monostable
Actuation type	Electrical
Standard nominal flow rate	46 l/min
Pneumatic working port	M5
Operating pressure	0 MPa ... 0.65 MPa
Operating pressure	0 bar ... 6.5 bar
Structural design	Plate seat
Reset method	Mechanical spring
Certification	c UL - Recognized (OL)
Nominal width	1.5 mm
Type code	MOFH
Exhaust air function	Without flow control option
Sealing principle	Soft
Mounting position	Any
Manual override	Detenting
Type of control	Direct
Flow direction	Non-reversible
Symbol	00991322
Switching time off	8.5 ms
On switching time	12 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Temperature of medium	-15 °C ... 60 °C
Ambient temperature	-15 °C ... 40 °C
Type of mounting	With through-hole
Pneumatic connection 1	M5
Pneumatic connection 2	M5
Pneumatic connection 3	M5