


**Ball valve**  
**VZBE-11/2-T-63-F-3T-F0507-V15V15**  
 Part number: 4834302

**FESTO**

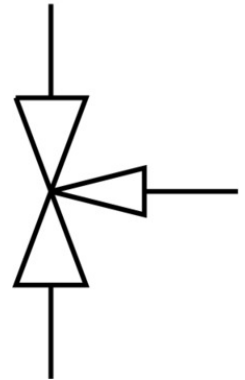

**Data sheet**

| Feature                                                                 | Value                                                                                          |
|-------------------------------------------------------------------------|------------------------------------------------------------------------------------------------|
| Type code                                                               | VZBE                                                                                           |
| Structural design                                                       | 3-way ball valve<br>Drilled T hole                                                             |
| Actuation type                                                          | Mechanical                                                                                     |
| Sealing principle                                                       | Soft                                                                                           |
| Mounting position                                                       | Any                                                                                            |
| Type of mounting                                                        | Line installation                                                                              |
| Fitting connection                                                      | 1 1/2 NPT                                                                                      |
| Switching position indication                                           | Slot direction = flow direction                                                                |
| Flange hole pattern                                                     | F0507                                                                                          |
| Inside diameter                                                         | 32 mm                                                                                          |
| Nominal width DN                                                        | 40                                                                                             |
| Valve function                                                          | 3/2                                                                                            |
| Flow direction                                                          | Reversible                                                                                     |
| Nominal pressure of fitting PN                                          | 63                                                                                             |
| Breakaway torque at differential pressure, nominal pressure, fitting PN | 45.5 Nm                                                                                        |
| Based on norm                                                           | ASME B1.20.1<br>ISO 5211                                                                       |
| Symbol                                                                  | 00991888                                                                                       |
| Medium                                                                  | Vapor<br>Compressed air as per ISO 8573-1:2010 [:-:-]<br>Inert gas<br>Water<br>Neutral liquids |
| Temperature of medium                                                   | -20 °C ... 200 °C                                                                              |
| Flow rate Kv type T corner                                              | 76 m³/h                                                                                        |
| Note on materials                                                       | Contains paint-wetting impairment substances<br>RoHS-compliant                                 |
| Housing material                                                        | Cast stainless steel                                                                           |
| Material number of housing                                              | 1.4408                                                                                         |
| Seat seal material                                                      | PTFE                                                                                           |

| Feature                                    | Value                                                              |
|--------------------------------------------|--------------------------------------------------------------------|
| Seals material                             | PTFE                                                               |
| Ball material                              | Cast stainless steel                                               |
| Material number for ball                   | 1.4408                                                             |
| Shaft material                             | High-alloy stainless steel                                         |
| Material number for shaft                  | 1.4401                                                             |
| Product weight                             | 3360 g                                                             |
| Certification                              | CRN                                                                |
| CE marking (see declaration of conformity) | as per EU pressure equipment directive                             |
| Explosion prevention and protection        | Zone 1 (ATEX)<br>Zone 2 (ATEX)<br>Zone 21 (ATEX)<br>Zone 22 (ATEX) |
| Corrosion resistance class (CRC)           | 4 - Particularly high corrosion stress                             |