


Quick coupling
EAMD-56-46-18-23X27
Part number: 5063729

FESTO

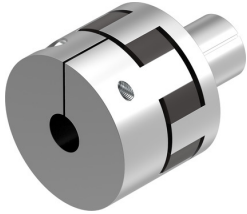

Data sheet

Feature	Value
Diameter of holder 1	18 mm
Diameter of holder 2	23 mm
Size	56
Nominal length	46.5 mm
Type code	EAMD
Mounting position	Any
Max. rotational speed	5500 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	151 kgmm ²
Transferable torque	57 Nm
Product weight	419 g
Note on materials	RoHS-compliant