


# Manifold MHA4-PR2-3-1/4

Part number: 525234

FESTO

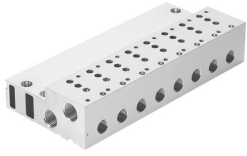

## Data sheet

Feature	Value
Type code	MH4
Max. no. of valve positions	2
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Product weight	440 g
Sub-base mounting type	With through-hole With H-rail
Pneumatic valve mounting type	With internal thread
Pneumatic connection 1/33	G3/8
Pneumatic connection 2	Internal thread G1/4
Pneumatic connection 3/11	G3/8
Note on materials	Free of copper and PTFE
Material of sub-base	Wrought aluminum alloy