
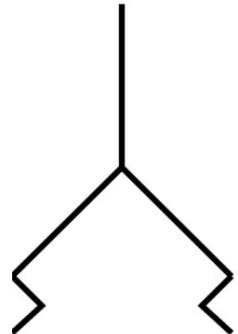


Vacuum suction cup ESS-50-GT-G1/4

Part number: 525979

FESTO

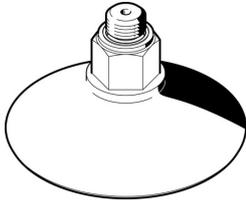

Data sheet

Feature	Value
Suction cup holder height compensator	8 mm
Min. workpiece radius	40 mm
Nominal width	2.5 mm
Suction cup diameter	50 mm
Suction cup volume	11.2 cm ³
Type code	ESS
Mounting position	Any
Symbol	00991485
Suction cup shape	Round, deep
Operating pressure	-0.95 bar ... 0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 80 °C
Holding force at nominal operating pressure	97 N
Lateral force at nominal operating pressure	30 N
Product weight	21 g
Type of mounting	Via vacuum connection
Vacuum connection	G1/4
Color	Reddish brown
Shore hardness	72 +/- 5
Material of screwed trunion	Wrought aluminum alloy
Note on materials	Free of copper and PTFE RoHS-compliant
Suction cup material	Vulkollan®