


Vacuum suction cup ESS-50-BT-M6

Part number: 525993

FESTO

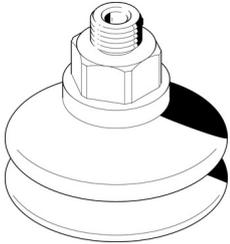

Data sheet

Feature	Value
Suction cup holder height compensator	10 mm
Min. workpiece radius	40 mm
Nominal width	2.5 mm
Suction cup diameter	50 mm
Suction cup volume	17.6 cm ³
Type code	ESS
Mounting position	Any
Symbol	00991485
Classification of suction cup holder	Size 4
Suction cup shape	Round bellows, 1.5 convolutions
Operating pressure	-0.95 bar ... 0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 80 °C
Holding force at nominal operating pressure	100 N
Lateral force at nominal operating pressure	39 N
Product weight	24 g
Type of mounting	Via vacuum connection
Vacuum connection	M6
Color	Reddish brown
Shore hardness	72 +/- 5
Material of screwed trunnion	Wrought aluminum alloy
Note on materials	Free of copper and PTFE RoHS-compliant
Suction cup material	Vulkollan®