


Pressure regulator LR-QS6-D-O-7-MICRO

Part number: 526272

FESTO

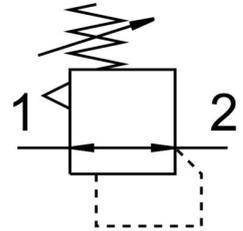

Data sheet

Feature	Value
Size	Micro
Type code	LR
Series	D
Actuator lock	Rotary knob with detent
Mounting position	Any
Structural design	Directly controlled diaphragm regulator
Controller function	With secondary exhausting
Symbol	00991540
Pressure gauge	M5 prepared
Operating pressure	1 bar ... 10 bar
Pressure regulation range	0.5 bar ... 7 bar
Max. pressure hysteresis	0.3 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	100 g
Type of mounting	Optionally: Line installation With accessories
Pneumatic connection 1	QS-6
Pneumatic connection 2	QS-6
Note on materials	RoHS-compliant
Material of sub-base	Wrought aluminum alloy
Seals material	NBR
Housing material	Wrought aluminum alloy
Diaphragm material	NBR