


Air line lubricator LOE-QS6-D-MICRO

Part number: 526314

FESTO

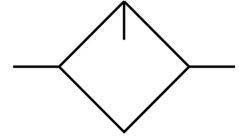

Data sheet

Feature	Value
Size	Micro
Type code	LOE
Series	D
Mounting position	Vertical +/- 5°
Structural design	Proportional standard oil mist lubricator
Max. oil capacity	6.5 cm ³
Symbol	00991532
Operating pressure	1 bar ... 10 bar
Minimum flow rate for lubricator function	3 l/min
Standard nominal flow rate	330 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:4:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	59 g
Type of mounting	Optionally: Line installation With accessories
Pneumatic connection 1	QS-6
Pneumatic connection 2	QS-6
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum
Material of bowl	PC