


Air preparation unit FRC-QS4-D-7-5M-MICRO-H

Part number: 527877

FESTO

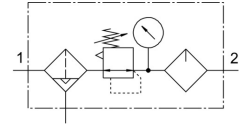

Data sheet

| Feature | Value |
|---------------------------|---|
| Size | Micro |
| Type code | FRC |
| Series | D |
| Actuator lock | Rotary knob with detent |
| Mounting position | Vertical +/- 5° |
| Condensate drain | Semi-automatic |
| Structural design | Filter regulator with pressure gauge Proportional standard oil mist lubricator |
| Max. condensate volume | 3 ml |
| Grade of filtration | 5 µm |
| Symbol | 00991509 |
| Pressure gauge | with pressure gauge |
| Operating pressure | 1 bar ... 10 bar |
| Pressure regulation range | 0.5 bar ... 7 bar |
| Max. pressure hysteresis | 0.3 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [-:-:-] |
| Temperature of medium | -10 °C ... 60 °C |
| Ambient temperature | -10 °C ... 60 °C |
| Product weight | 149 g |
| Type of mounting | Line installation With accessories |
| Pneumatic connection 1 | QS-4 |
| Pneumatic connection 2 | QS-4 |
| Housing material | Wrought aluminum alloy |
| Material of bowl | PC |