


Quick coupling EAMC-65-90-15-24

Part number: 530940

FESTO

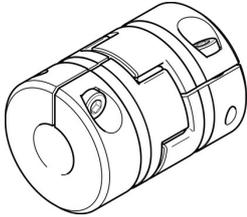

Data sheet

Feature	Value
Diameter of holder 1	15 mm
Diameter of holder 2	24 mm
Size	65
Nominal length	90 mm
Type code	EAMC
Mounting position	Any
Max. rotational speed	4500 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	417 kgmm ²
Transferable torque	80 Nm
Product weight	535 g
Note on materials	RoHS-compliant