


Fine filter combination LFMBA-3/4-D-MAXI-DA-A

Part number: 532881

FESTO



Data sheet

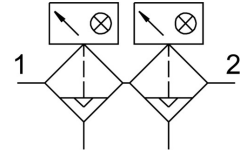

Feature	Value
Size	Maxi
Type code	LFMBA
Series	D
Mounting position	Vertical +/- 5°
Grade of filtration	0.01 µm
Filter efficiency	99.9999 %
Condensate drain	Fully automatic
Structural design	Fiber filter
Max. condensate volume	80 ml
Bowl guard	Metal bowl guard
Symbol	00991530
Operating pressure	1.5 bar ... 12 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [6:8:4] Inert gas
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [1:7:2] Inert gas
Temperature of medium	1.5 °C ... 60 °C
Residual oil content	0.01 mg/m³
Ambient temperature	-10 °C ... 60 °C
Product weight	2362 g
Type of mounting	Line installation With accessories
Pneumatic connection 1	G3/4
Pneumatic connection 2	G3/4
Note on materials	Free of copper and PTFE RoHS-compliant
Compressed air filter material	Borosilicate fiber
Housing material	Die-cast zinc
Material of bowl	PC