


# Plug FBS-SUB-9-GS-1X9POL-B

Part number: 534497

FESTO

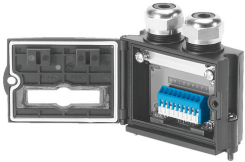

## Data sheet

Feature	Value
Width	20 mm
Height	62 mm
Length	61 mm
Type code	FBS
Product weight	60 g
Fieldbus interface	1x 9 spring-loaded terminals
Approved cable diameter	5 mm ... 10 mm
Degree of protection	IP65 IP67 In mounted state as per IEC 60529
Ambient temperature	0 °C ... 50 °C
Storage temperature	-20 °C ... 70 °C
Relative air humidity	95 % Non-condensing
CE marking (see declaration of conformity)	As per EU EMC directive As per EU low voltage directive
Housing material	PA-reinforced
Material of union nut	Brass
Material of screws	Steel
Seals material	NBR