


Active carbon filter MS4-LFX-1/8-U

Part number: 536709

FESTO

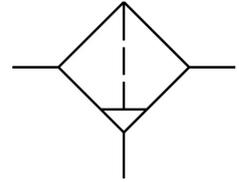

Data sheet

Feature	Value
Size	4
Type code	MS4-LFX
Series	MS
Mounting position	Vertical +/- 5°
Structural design	Active carbon filter
Bowl guard	Integrated as metal bowl guard
Symbol	00991519
Operating pressure	0 bar ... 14 bar
Max. standard flow rate for air quality class	360 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [1:4:2] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [1:4:1]
Temperature of medium	5 °C ... 30 °C
Residual oil content	0.003 mg/m ³
Ambient temperature	-10 °C ... 60 °C
Product weight	350 g
Type of mounting	Optionally: Line installation With accessories
Pneumatic connection 1	G1/8
Pneumatic connection 2	G1/8
Note on materials	Free of copper and PTFE RoHS-compliant
Compressed air filter material	Activated carbon
Housing material	Die-cast aluminum
Material of bowl	Die-cast aluminum Wrought aluminum alloy
Inspection window material	PA