


Branching module MS4-FRM-1/4-I

Part number: 536966

FESTO

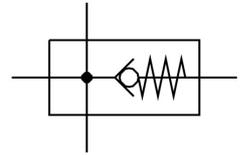

Data sheet

Feature	Value
Type code	MS4-FRM
Mounting position	Any
Structural design	Branching module with non-return function
Symbol	00991511
Operating pressure	0 bar ... 10 bar
Standard nominal flow rate in main flow direction 1 -> 2	1750 l/min
Standard nominal flow rate outlet at top	500 l/min
Standard nominal flow rate outlet down	500 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
For use in the food industry	See supplementary material information
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	160 g
Pneumatic connection 1	G1/4
Pneumatic connection 2	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 4	G1/4
Note on materials	Free of copper and PTFE RoHS-compliant
Housing material	Die-cast aluminum