


Sub-base VMPA2-IC-AP-1

Part number: 537981

FESTO

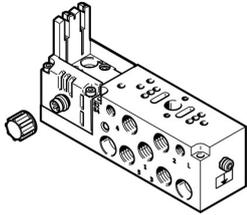

Data sheet

Feature	Value
Width	30.5 mm
Length	107.3 mm
Width dimension	21 mm
Type code	VMPA2
Operating pressure	0.3 MPa ... 0.8 MPa
Operating pressure	3 bar ... 8 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Certification	c UL us - Recognized (OL)
KC characters	KC EMC
CE marking (see declaration of conformity)	As per EU EMC directive
Corrosion resistance class (CRC)	0 - No corrosion stress
Ambient temperature	-5 °C ... 50 °C
Product weight	233 g
Electrical connection	M8 Plug
Sub-base mounting type	With through-hole
Pneumatic connection 1	G1/8
Pneumatic connection 2	G1/8
Pneumatic connection 3	G1/8
Pneumatic connection 4	G1/8
Pneumatic connection 5	G1/8
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum