


Connecting cable NEBV-S1G25-K-10-N-LE25

Part number: 538227

FESTO

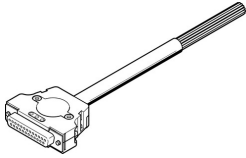

Data sheet

Feature	Value
Type code	NEBV
Type of mounting	4-40 UNC-2B
Product weight	1750 g
Electrical connection 1	Sub-D socket, 25-pin
Electrical connection 2	Open end, 25-wire
Nominal operating voltage DC	24 V
Cable length	10 m
Cable characteristic	Standard
Min. cable bending radius	105 mm
Cable diameter	10.5 mm
Cable design	20 x 0.25 mm ² + 5 x 0.34 mm ²
Degree of protection	IP65 IP67 In mounted state
Ambient temperature with flexible cable installation	-5 °C ... 50 °C
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Material of cable sheath	PVC
Housing material	PBT
Material of union nut	PA
Seals material	TPE-O