


# Moment compensator FKC-40

Part number: 538962

FESTO

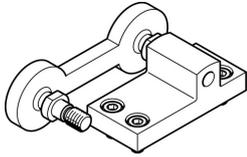

## Data sheet

Feature	Value
Size	40
Radial deviation +/-	2.5 mm
Type code	FKC
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 60 °C
Short-term maximum permissible load in direction of force +/-	3000 N
Long-term maximum permissible load in direction of force +/-	1400 N
Product weight	180.2 g
Note on materials	RoHS-compliant
Articulated joint material	PA-reinforced
Ball stud material	High-alloy steel
Plate material	Wrought aluminum alloy