 



# Vertical pressure supply plate VABF-S4-2-P1A3-N18

FESTO

Part number: 540174

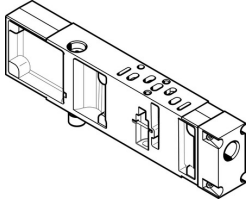

## Data sheet

Feature	Value
Width	18 mm
Type code	VABF
Based on norm	ISO 15407-2
Mounting position	Any
Symbol	00991883
Operating pressure	1 MPa
Operating pressure	10 bar
CE marking (see declaration of conformity)	As per EU low voltage directive
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
Degree of protection	IP65 NEMA 4
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Ambient temperature	-5 °C ... 50 °C
Product weight	140 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Pneumatic connection 1	1/8 NPT
Housing material	Die-cast aluminum