


# Pneumatic shock absorber YSRW-DGC-12

Part number: 540345

FESTO

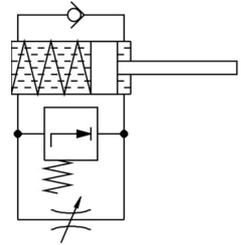

## Data sheet

Feature	Value
Size	12
Type code	YSRW-DGC
Cushioning	Self-adjusting Soft characteristic curve
Mounting position	Any
Position sensing	None
Symbol	00991497
Max. impact velocity	2 m/s
Mode of operation	Single-acting Pushing
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 80 °C
Type of mounting	With lock nut
Note on materials	Free of copper and PTFE RoHS-compliant
Piston rod material	High-alloy steel