


# Shut off valve MS4-EM1-1/8-S

Part number: 541263

**FESTO**

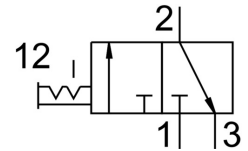

## Data sheet

| Feature                                  | Value                                                              |
|------------------------------------------|--------------------------------------------------------------------|
| Type code                                | MS4-EM1                                                            |
| Structural design                        | Rotary gate valve                                                  |
| Actuation type                           | Manual                                                             |
| Exhaust air function                     | Without flow control option                                        |
| Type of control                          | Direct                                                             |
| Symbol                                   | 00991670                                                           |
| Valve function                           | 3/2, bistable                                                      |
| Operating pressure                       | 0 bar ... 14 bar                                                   |
| C value                                  | 4.6 l/sbar                                                         |
| b-value                                  | 0.51                                                               |
| Standard nominal flow rate               | 1200 l/min                                                         |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:4:4]<br>Inert gas         |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)         | 2 - Moderate corrosion stress                                      |
| Note on materials                        | Free of copper and PTFE<br>RoHS-compliant                          |
| Temperature of medium                    | -10 °C ... 60 °C                                                   |
| Ambient temperature                      | -10 °C ... 60 °C                                                   |
| For use in the food industry             | See supplementary material information                             |
| Type of mounting                         | Optionally:<br>Line installation<br>With accessories               |
| Mounting position                        | Any                                                                |
| Flow direction                           | Non-reversible                                                     |
| Product weight                           | 210 g                                                              |
| Pneumatic connection 1                   | G1/8                                                               |
| Pneumatic connection 2                   | G1/8                                                               |
| Pneumatic connection 3                   | Not ducted                                                         |
| Seals material                           | TPE-U(PU)                                                          |
| Housing material                         | Die-cast aluminum                                                  |