


Intermediate position module DADM-DGC-25-A

Part number: 541700

FESTO

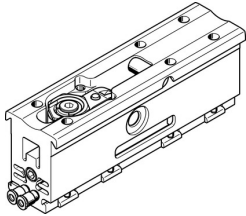

Data sheet

Feature	Value
Size	25
Type code	DADM-DGC
Mounting position	Any
Position sensing	For proximity sensor
Operating pressure	2.5 bar ... 8 bar
Max. impact velocity	3 m/s
Maximum pivot time	100 ms
Repetition accuracy	0.02 mm
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 60 °C
Product weight	430 g
Type of mounting	Clamped on cylinder DGC
Pneumatic connection	QS-4
Note on materials	Free of copper and PTFE RoHS-compliant
Stop screw material	Steel Galvanized
Seals material	NBR
Housing material	Wrought aluminum alloy Anodized
Lever material	High-alloy stainless steel
Clip material	High-alloy stainless steel
Nut material	Steel Galvanized
Precision adjustment	2 mm
Mode of operation	Double-acting