


# Vacuum security valve ISV-M4

Part number: 545996

FESTO

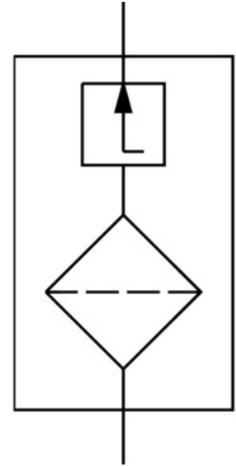

## Data sheet

Feature	Value
Size	M4
Type code	ISV
Ejector pulse suitability	≤0.8 MPa
Ejector pulse suitability	≤8 bar
Mounting position	Any
Symbol	00991481
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Required suction rate at -0.5 bar	1 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 60 °C
Product weight	1.5 g
Type of mounting	Screw-in
Pneumatic connection 1	M4
Pneumatic connection 2	M4
Compressed air filter material	Sintered bronze
Housing material	Wrought aluminum alloy