


Basic valve LF-D-MIDI-U

Part number: 546422

FESTO

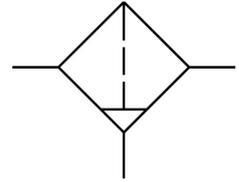

Data sheet

Feature	Value
Size	Midi
Type code	LF
Series	D
Mounting position	Vertical +/- 5°
Grade of filtration	40 µm
Condensate drain	Manually rotating
Structural design	Sinter filter with centrifugal separator
Max. condensate volume	42.983 ml
Bowl guard	Metal bowl guard
Symbol	00991519
Operating pressure	0 bar ... 16.547 bar
Standard nominal flow rate	12012.71 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [-:9:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:8:4] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	694.575 g
Type of mounting	Optionally: Line installation With mounting bracket
Note on materials	RoHS-compliant
Compressed air filter material	PE
Housing material	Die-cast zinc
Material of bowl	PC