


Plug socket with cable KMEB-3-24-2.5-LED

Part number: 547268

FESTO

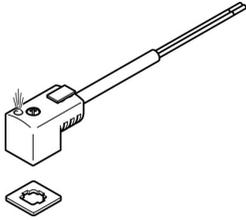

Data sheet

Feature	Value
Type code	KMEB
Switching status indication	LED yellow
Type of mounting	On air solenoid valve with M2.5 central screw
Mounting position	Any
Product weight	120 g
Electrical connection	2-pin Socket, angled Form C as per DIN EN 175301-803
Nominal operating voltage DC	24 V
Reverse polarity protection	for all electrical connections
Protective earth connection	Not available
Cable length	2.5 m
Cable characteristic	Standard
Cable diameter	5.2 mm
Cable design	2 x 0.75 mm ²
Degree of protection	IP65 as per IEC 60529
Ambient temperature	-20 °C ... 80 °C
CE marking (see declaration of conformity)	As per EU RoHS directive
Corrosion resistance class (CRC)	1 - Low corrosion stress
Material of cable sheath	PVC
Housing material	PC
Material of pin contacts	Bronze Silver-plated