


Regulator plate VMPA1-B8-R1C2-C-06

Part number: 549052

FESTO

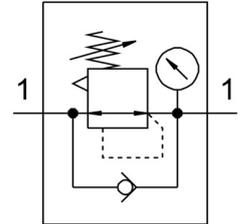

Data sheet

Feature	Value
Width	10.5 mm
Type code	VMPA1
Mounting position	Any
Pneumatic vertical stacking	Pressure regulator for 1
Controller function	Outlet pressure constant With secondary exhausting
Symbol	00992000
Optional pressure gauge	Possible
Pressure regulation range	0.5 bar ... 6 bar
Inlet pressure 1	0.5 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	1 - Low corrosion stress
Degree of protection	IP65 as per IEC 60529
Ambient temperature	-5 °C ... 50 °C
Max. tightening torque	0.25 Nm
Product weight	73.8 g
Vertical stacking mounting type	On manifold sub-base
Pressure gauge connection	M5
Note on materials	RoHS-compliant
Material of operator panel	PA
Seals material	NBR
Controller housing material	PA