


Connecting cable NEBC-P1W4-K-0.3-N-M12G5

Part number: 549293

FESTO

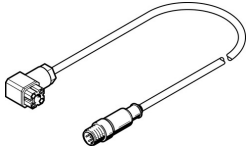

Data sheet

Feature	Value
Type code	NEBC
Based on norm	EN 61076-2-101
Electrical connection	5-pin M12x1 Plug, straight Square design/angled
Protective earth connection	Available
Cable length	0.3 m
Min. cable bending radius	90 mm
Cable diameter	5.9 mm
Approved cable diameter	5.7 mm ... 6.1 mm
Cable design	4 x 0.34 mm ²
Nominal conductor cross section	0.34 mm ²
Degree of protection	IP65
Ambient temperature	-25 °C ... 85 °C
Ambient temperature with flexible cable installation	-25 °C ... 85 °C
Corrosion resistance class (CRC)	0 - No corrosion stress
Material of cable sheath	PVC TPE-U(PUR)
Color cable sheath	Gray
Housing colour	Black