
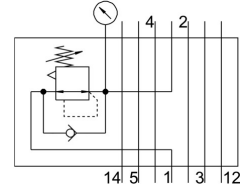


# Regulator plate VABF-S4-1-R1C2-C-6E

Part number: 549876

FESTO

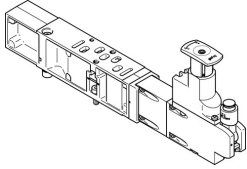

## Data sheet

Feature	Value
Width	26 mm
Type code	VABF
Based on norm	ISO 15407-2
Mounting position	Any
Controller function	Outlet pressure constant With secondary exhausting
Symbol	00992227
Optional pressure gauge	Possible
Operating pressure	0.6 MPa
Operating pressure	6 bar
Pressure regulation range	0.5 bar ... 6 bar
Inlet pressure 1	0.5 bar ... 10 bar
CE marking (see declaration of conformity)	As per EU low voltage directive
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
Degree of protection	IP65 NEMA 4
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Ambient temperature	-5 °C ... 50 °C
Product weight	445 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Pressure gauge connection	With retaining clamp
Material of operator panel	PA
Controller housing material	Die-cast aluminum