


Axial kit EAMM-A-D32-57A

Part number: 550980

FESTO

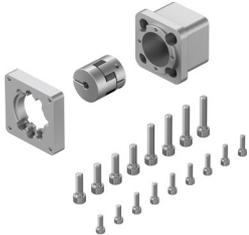

Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	6.5 Nm
Product weight	270 g
Interface code, actuator	D32A D32B D32C
Interface code, motor in	57A
Note on materials	Contains paint-wetting impairment substances RoHS-compliant