


# Axial kit EAMM-A-D40-70A

Part number: 550981

FESTO

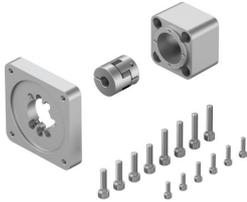

## Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	12.5 Nm
Product weight	410 g
Interface code, actuator	D40A D40B D40C
Interface code, motor in	70A
Note on materials	Contains paint-wetting impairment substances RoHS-compliant