


Fiber-optic cable SOOC-DS-Q-2-R25

Part number: 552811

FESTO

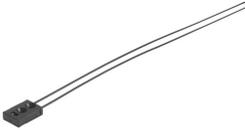

Data sheet

| Feature | Value |
|--------------------------------------|---------------------------|
| Type code | SOOC |
| Note on materials | RoHS-compliant |
| Method of measurement | Fix-focus |
| Minimum object diameter | 0.1 mm |
| Special feature of fibre-optic cable | Fix-focus |
| Working range | 2 mm ... 10 mm |
| Ambient temperature | -55 °C ... 70 °C |
| Head size | Rectangle 13x19.6x5 mm |
| Fibre-optic cable length | 2 m |
| Min. bending radius | 25 mm |
| Outside diameter | 2.2 mm |
| Housing material | ABS |
| Fiber-optic cable | PE |
| Degree of protection | IP66 |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| LABS conformity | VDMA24364 zone III |