


Fiber-optic cable SOOC-TB-P-M3-1-R10

Part number: 552821

FESTO

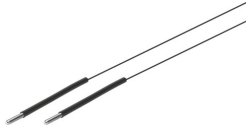

Data sheet

Feature	Value
Type code	SOOC
Note on materials	RoHS-compliant
Method of measurement	Through-beam sensor
Minimum object diameter	0.05 mm
Special feature of fibre-optic cable	Precision
Working range	30 mm
Ambient temperature	-55 °C ... 70 °C
Head size	M3
Fibre-optic cable length	1 m
Min. bending radius	10 mm
Max. tightening torque	1 Nm
Outside diameter	1 mm
Housing material	High-alloy stainless steel
Fiber-optic cable	PE
Degree of protection	IP66
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS conformity	VDMA24364 zone III