


# Vacuum filter VAF-DB-1/2

Part number: 553141

FESTO

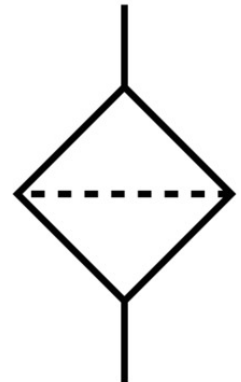

## Data sheet

| Feature                           | Value                                                          |
|-----------------------------------|----------------------------------------------------------------|
| Type code                         | VAF                                                            |
| Mounting position                 | Vertical                                                       |
| Grade of filtration               | 80 µm                                                          |
| Symbol                            | 00991483                                                       |
| Operating pressure                | -0.95 bar ... 0 bar                                            |
| Information on operating pressure | Only for use in open vacuum systems                            |
| Operating medium                  | Compressed air as per ISO 8573-1:2010 [7:::]                   |
| Ambient temperature               | -5 °C ... 50 °C                                                |
| Max. tightening torque            | 20.5 Nm                                                        |
| Product weight                    | 162 g                                                          |
| Type of mounting                  | Line installation<br>With wall/surface bracket                 |
| Pneumatic connection              | G1/2                                                           |
| Vacuum connection                 | G1/2                                                           |
| Note on materials                 | Contains paint-wetting impairment substances<br>RoHS-compliant |
| Seals material                    | NBR                                                            |
| Compressed air filter material    | PE                                                             |
| Housing material                  | PP-reinforced                                                  |
| Material of bowl                  | PA                                                             |
| Ejector pulse suitability         | ≤7 bar                                                         |