 



# Vertical pressure supply plate VABF-S2-2-P1A3-G12

FESTO

Part number: 555786

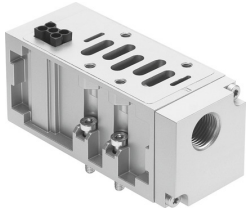

## Data sheet

| Feature                                  | Value  |
|--|--|
| Width                                    | 54 mm  |
| Type code                                | VABF   |
| Based on norm                            | ISO 5599-2   |
| Mounting position                        | Any  |
| Pneumatic vertical stacking              | Alternative pressure supply for 1                                  |
| Symbol                                   | 00991883   |
| Operating pressure                       | -0.09 MPa ... 1 MPa  |
| Operating pressure                       | -0.9 bar ... 10 bar  |
| Inlet pressure 1                         | 0.5 bar ... 10 bar   |
| Inlet pressure 1 MPa                     | 0.05 MPa ... 1 MPa   |
| Inlet pressure 1 psi                     | 7.25 psi ... 145 psi   |
| Standard nominal flow rate               | 2800 l/min   |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)         | 0 - No corrosion stress  |
| Degree of protection                     | IP65<br>NEMA 4   |
| Ambient temperature                      | -5 °C ... 50 °C  |
| Product weight                           | 605 g  |
| Vertical stacking mounting type          | On manifold sub-base<br>On individual sub-base                     |
| Pneumatic connection 1                   | G1/2   |
| Note on materials                        | RoHS-compliant   |
| Housing material                         | Die-cast aluminum  |