


# Manifold rail MHJ10-P16

Part number: 557608

FESTO

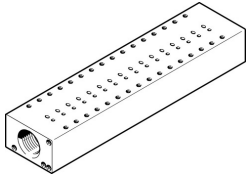

## Data sheet

| Feature                          | Value  |
|----------------------------------|--|
| Width dimension                  | 11 mm  |
| Type code                        | MHJ10  |
| Reverse polarity protection      | for operating voltage  |
| Max. no. of valve positions      | 16<br>Versions according to customer specifications possible |
| Certification                    | RCM compliance mark  |
| KC characters                    | KC EMC   |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress                                |
| Product weight                   | 635 g  |
| Type of mounting                 | With mounting bracket  |
| Pneumatic connection 1           | G1/2   |
| Pneumatic connection 2           | M7   |
| Note on materials                | RoHS-compliant   |
| Manifold rail material           | Wrought aluminum alloy<br>Anodized                           |