


Motor flange
EAMF-A-48A-60G/H
Part number: 558019

FESTO

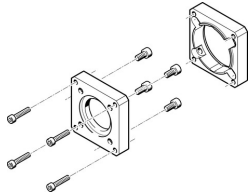

Data sheet

Feature	Value
Type code	EAMF-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-10 °C ... 60 °C
Interface code, motor in	60G 60H
Interface code, coupling housing	48A
Note on materials	RoHS-compliant