


# Connecting cable VMPAL-KMSK-S-SD25-IP67-10

FESTO

Part number: 560415

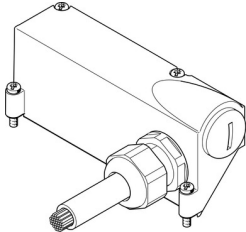

## Data sheet

Feature	Value
Type code	VMPAL
Product weight	2155 g
Electrical connection	Cable with plug
Cable length	10 m
Cable characteristic	Suitable for energy chains
Min. cable bending radius	63 mm
Cable diameter	12.5 mm
Cable design	25 x 0.34 mm <sup>2</sup>
Degree of protection	IP67 as per IEC 60529
Ambient temperature with flexible cable installation	-5 °C ... 80 °C
CE marking (see declaration of conformity)	As per EU RoHS directive
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Material of cable sheath	TPE-U(PU)