


# Axial kit EAMM-A-P4-28B-40A

Part number: 562637

FESTO

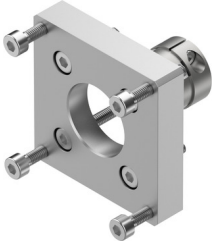

## Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	0.7 Nm
Product weight	50 g
Interface code, actuator	P4-28B
Interface code, motor in	40A
Interface code, coupling housing	28B
Note on materials	RoHS-compliant