


Quick coupling EAMC-16-20-3-6

Part number: 562671

FESTO

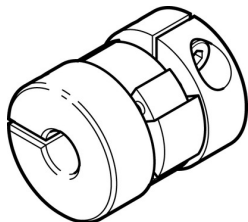

Data sheet

Feature	Value
Diameter of holder 1	3 mm
Diameter of holder 2	6 mm
Size	16
Nominal length	20 mm
Type code	EAMC
Mounting position	Any
Max. rotational speed	10000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	0.28 kgmm ²
Transferable torque	0.2 Nm
Product weight	8 g
Note on materials	RoHS-compliant