


# Quick coupling EAMC-16-20-5-5

Part number: 562676

FESTO

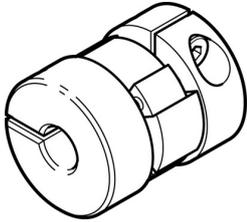

## Data sheet

Feature	Value
Diameter of holder 1	5 mm
Diameter of holder 2	5 mm
Size	16
Nominal length	20 mm
Type code	EAMC
Mounting position	Any
Max. rotational speed	10000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	0.28 kgmm <sup>2</sup>
Transferable torque	1.1 Nm
Product weight	8 g
Note on materials	RoHS-compliant