


End plate VMPAL-EPL-SD9-IP40

Part number: 570777

FESTO

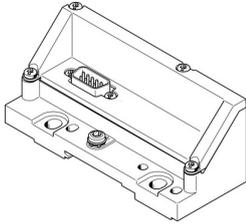

Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Type code	VMPAL
Max. no. of valve positions	8
Valve manifold design	Valve sizes can be mixed
Max. no. of solenoid coils	8
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Nominal operating voltage DC	24 V
Corrosion resistance class (CRC)	3 - High corrosion stress
Degree of protection	IP40
Note on degree of protection	In mounted state
Ambient temperature	-5 °C ... 50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Electrical connection for input 1, connection pattern	00995639
Note on materials	RoHS-compliant
End plate material	Die-cast aluminum PA-reinforced