


Fixed flow restrictor-SET VMPA1-FT-NW0.3-1.7

Part number: 572543

FESTO

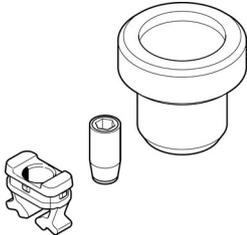

Data sheet

Feature	Value
Type code	VMPA
Valve function	Flow control function
Pneumatic connection 1	Sub-base
Standard nominal flow rate in flow control direction	3.5 l/min ... 115 l/min
Operating pressure	-0.9 bar ... 10 bar
Ambient temperature	-5 °C ... 60 °C
Nominal width	0.3 mm ... 1.7 mm
Mounting position	Any
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Storage temperature	-20 °C ... 40 °C
Temperature of medium	-5 °C ... 60 °C
Note on materials	RoHS-compliant
Retaining bracket material	POM
Hollow bolt material	Wrought aluminum alloy