


Power supply module VMPAL-SP-QS5/16"

Part number: 573646

FESTO

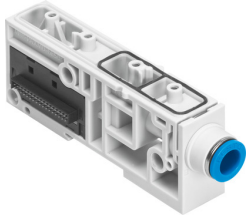

Data sheet

Feature	Value
Width	23.2 mm
Length	107.3 mm
Type code	VMPAL
Integrated function	With electrical manifold module
Valve manifold design	Valve sizes can be mixed
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class (CRC)	3 - High corrosion stress
Ambient temperature	-5 °C ... 50 °C
Product weight	50 g
Pneumatic connection 1	For pneumatic tubing outside diameter 5/16"
Note on materials	RoHS-compliant
Power supply module material	Wrought aluminum alloy PA-reinforced